



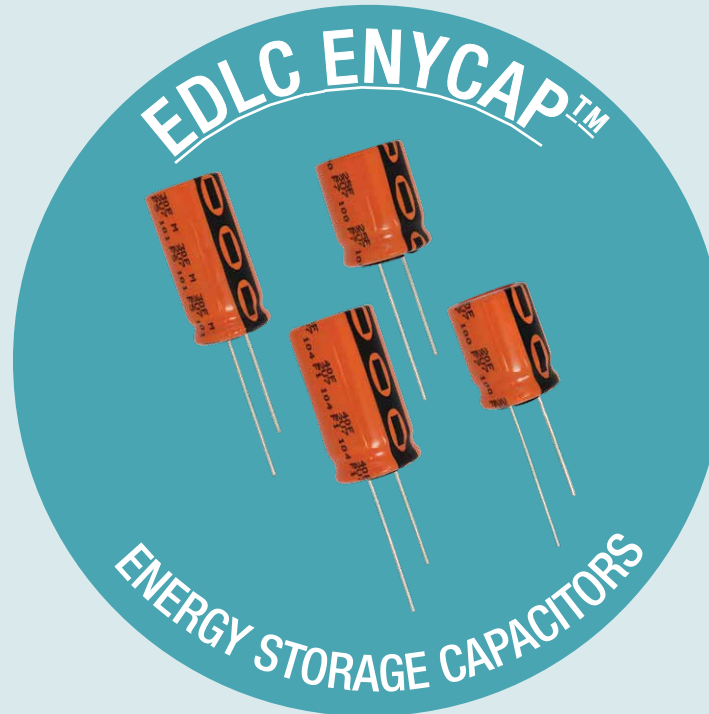

EDLC ENYCAP™



ELECTRICAL DOUBLE LAYER CAPACITORS

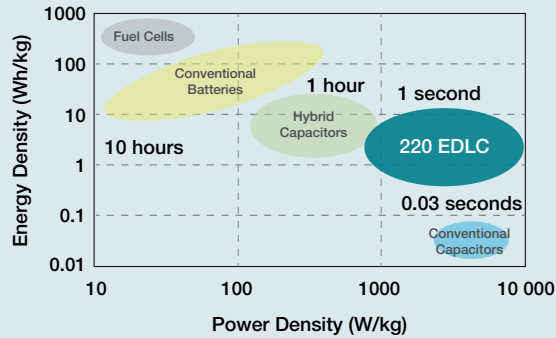


Features

- Useful life up to 2000 h at 85 °C
- High humidity 85 °C / 85 % RH
- High voltage up to 3 V
- AEC-Q200 qualified
- UL 810A recognized


Multiple Capacitance Values

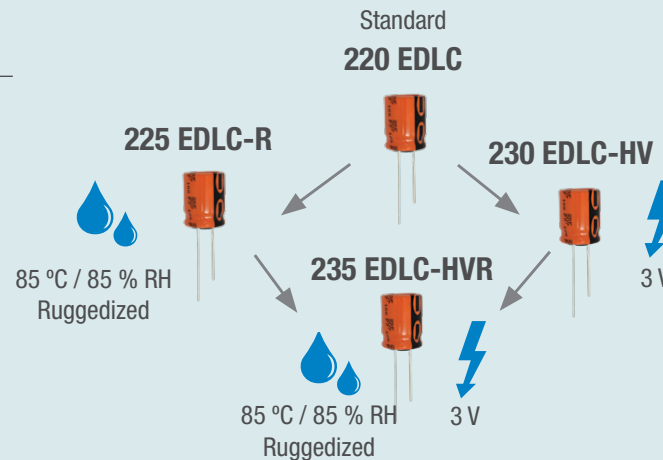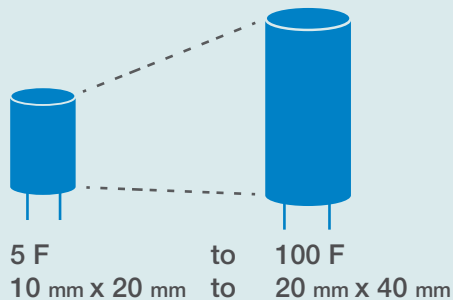

Power Back-Up

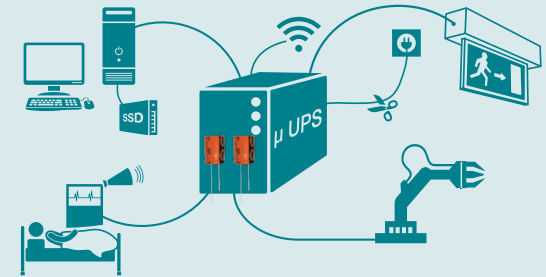

Burst Power Support

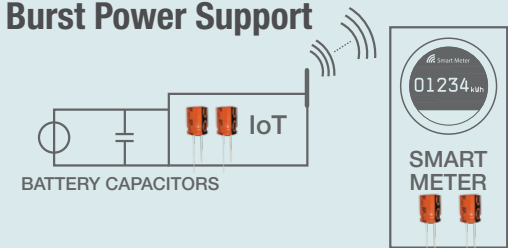

EDLC vs. Battery Cell

- Higher discharge current
- > 500 000 charge / discharge cycles
- Superfast charge and discharge
- Category temperature -40 °C to +85 °C

Voltage vs. Temperature

