




THICK FILM POWER RESISTORS

HIGH POWER, COMPACT THICK FILM RESISTORS

IN A NUTSHELL

	RCEC 750	WIREWOUND
	750 W	750 W
Size		
Footprint		
Weight	100 g	1400 g
Case Temp	70 °C	450 °C
Inductance	Non-inductive	Inductive
Resistance	0.3 Ω to 1 MΩ	8.2 Ω to 60 kΩ
Dielectric	Up to 12 kV	Not Insulated
Partial Discharge	< 5 pC	> 1000 pC

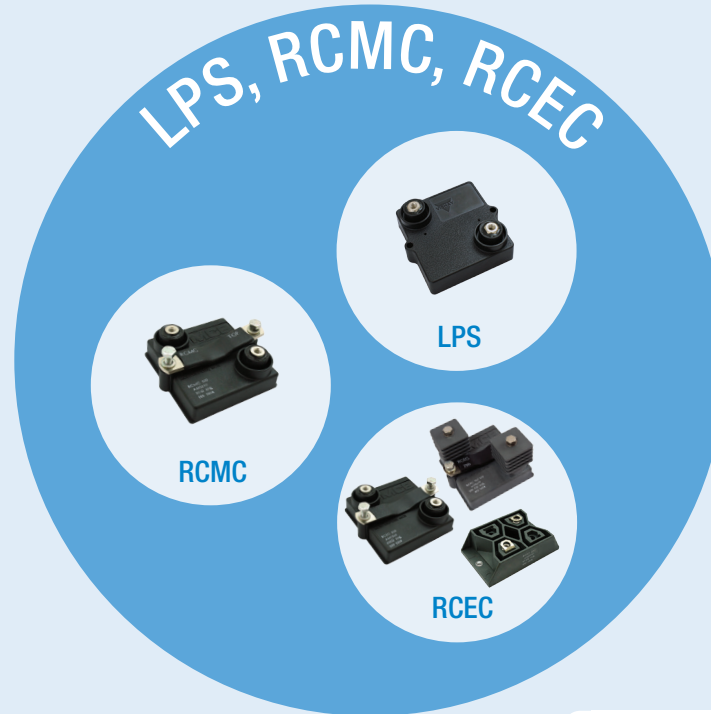

MEDICAL



SOLAR



INDUSTRY FIRST




30
Over
30 Years of
Experience

MARINE



WIND ENERGY
(GENERATION)

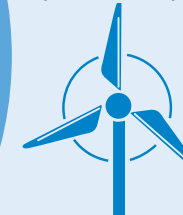

INDUSTRIAL



RAIL



DRIVES



HVDC
TRANSMISSION

LPS

RCMC

RCEC



CUSTOM FRIENDLY

- Specific terminals (size and diameter M4 - M5)
- Terminals with leads
- Possibility of two or three resistors in the same case (RCEC 400, RCEC 850)
- Creeping and clearance distances (HV version)
- Assemblies (resistors mounted on heatsink)

KEY APPLICATIONS

- ✓ Snubbers
- ✓ Discharge
- ✓ Balancing
- ✓ Dividers
- ✓ Filters

