





POWER ELECTRONIC CAPACITORS

HIGH CURRENT, VERY LOW INDUCTANCE

FOOTPRINT

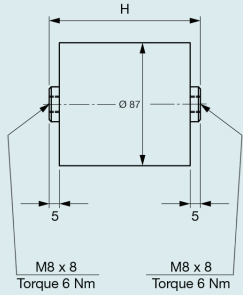

HEIGHT

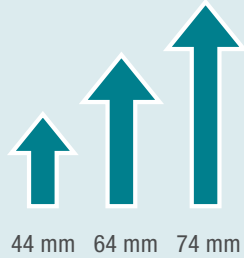

FEATURES

- Very low inductance
- Extremely low losses at high frequencies
- Low serial resistance
- High current ratings
- High impulse discharge current capability
- Resistance to heavy duty shock and vibration
- High reliability and life expectation

VOLTAGE DC

- 700 V to 2150 V or customizable



CAPACITANCE

- 11 μF to 230 μF



LIFE EXPECTANCY

- > 100 000 h
- < 300 FIT



FILLING AGENT

- ESTAdry resin
- UL 94 V-0



STANDARDS

IEC 61071, IEC 61881-1

RoHS
COMPLIANT

CONNECTION



SAFETY

- Self-healing film

 
APPLICATIONS



INDUSTRIAL



MEDICAL



DRIVES




TRANSPORTATION



UPS

VISHAY CAP MAP

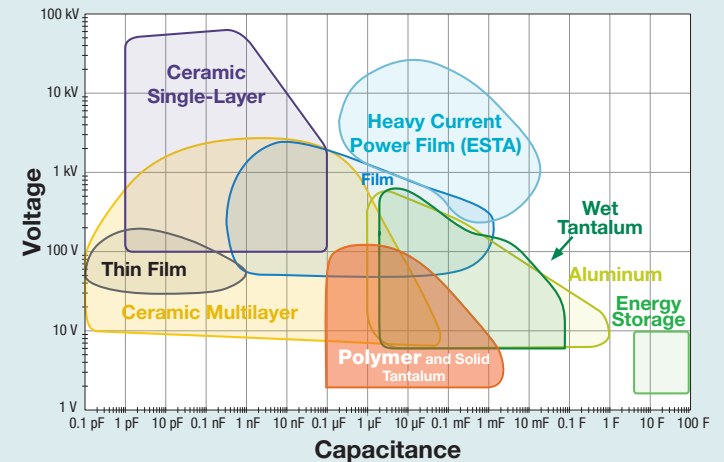

For technical questions: esta@vishay.com

© 2020 VISHAY INTERTECHNOLOGY, INC. ALL RIGHTS RESERVED.

IG16805987-2004