




多层陶瓷片式

高频射频和微波电容

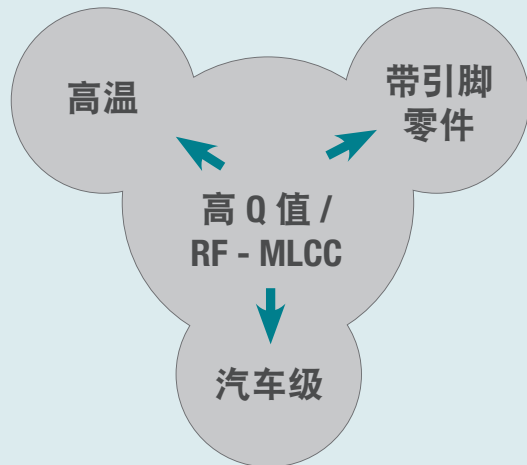


0402 0603 0805 0505 1111 2525 3838


	0402	0603	0805	0505	1111	2525	3838
标准	✓	✓	✓	✓	✓	✓	✓
高温	✓	✓	✓	✓	✓		
引线					✓	✓	✓
汽车级	✓	✓	✓	✓	✓		

端电极选项


- 无铅 (Pb), 符合 RoHS 标准: "X"
- 锡/铅 (最小 4% Pb) "L"
- 非磁性铜: "C"

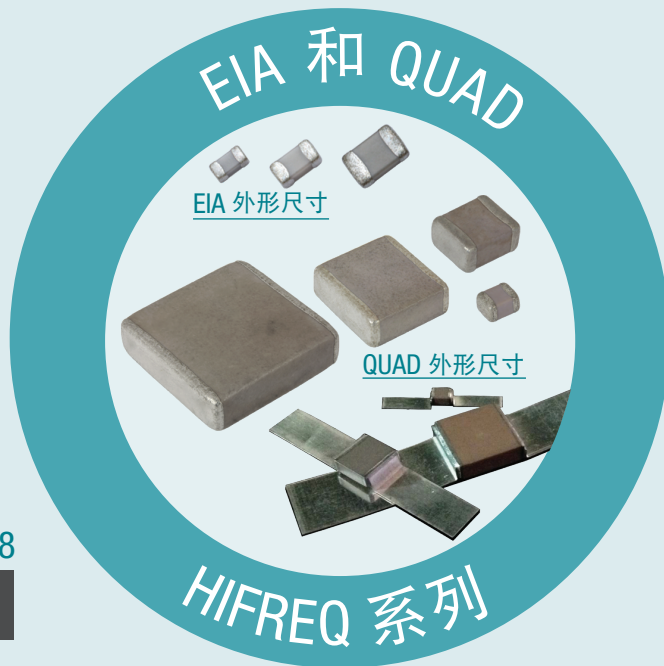

带引脚配置

 

微带

 

轴向带状物



径向带状物

设计资源

Modelithics®

cadence®



设计工具




S-参数



仿真工具

能够实现更大的输出功率水平的
VISHAY HIFREQ 系列

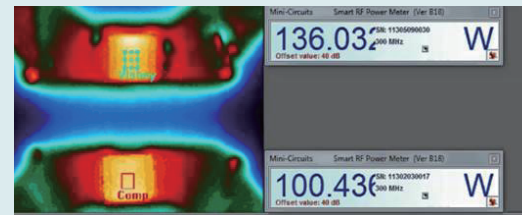

高温运行



应用



军用无线电



无线电源



5G 网络



仪表



设备和云连接



从 ADAS 到自动



通信