




# PowerPAK® 0806 Case Outline

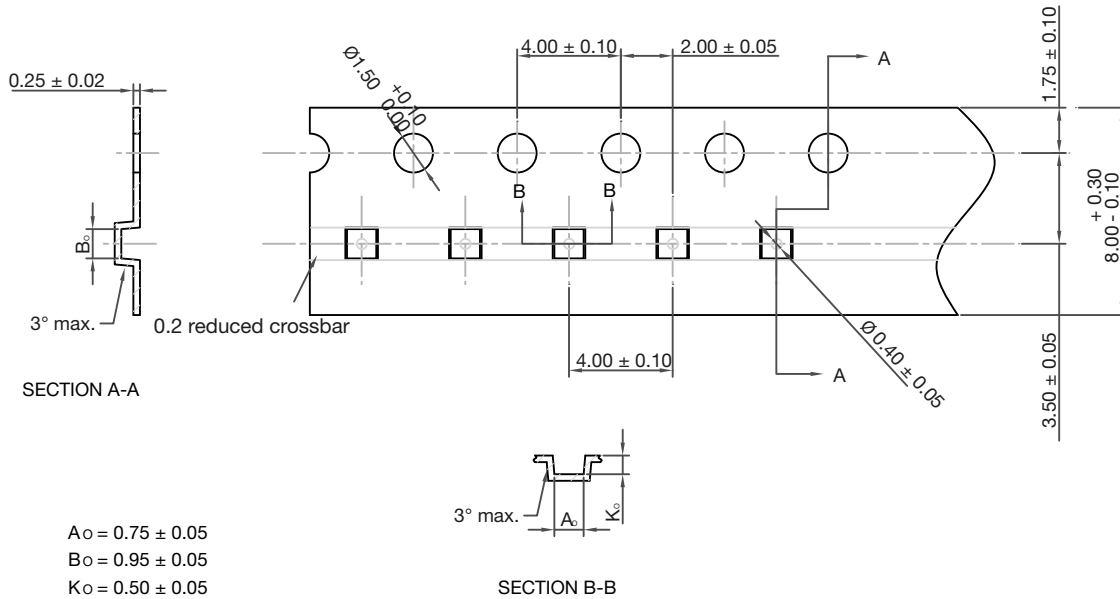

### Notes

- (1) 10 sprocket hole pitch cumulative tolerance ± 0.2 mm
- (2) Camber not to exceed 1 mm in 100 mm; camber also not to exceed 1 cm in 1 m actually
- (3) Pocket position relative to sprocket hole measured as true position of pocket, not pocket hole
- (4) Material: black conductive polycarbonate
- (5) All sizes in mm unless specified
- (6) Vishay part number must be labeled at all reels of cover and carrier tape
- (7) Surface resistivity: 10<sup>4</sup> to 10<sup>11</sup> Ω.

QUANTITY PER REEL	
T1	3000

ECN: C15-1434-Rev. C, 02-Nov-15 DWG: 93-5297-X
---