


Axial Series

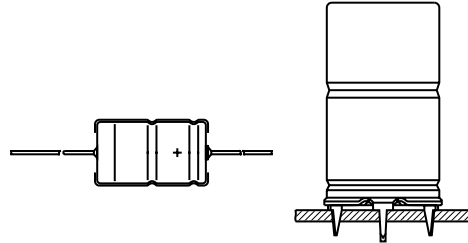

miniature diameter 3.3 mm
85 °C
<b>117 ASD</b>

non polar
105 °C
<b>EBU/EBT</b> on request

non polar
125 °C
<b>610 D</b>

standard ranges	
85 °C	105 °C
<b>021 ASM</b> <b>030/031 AS</b> <b>041-043 ASH</b> <b>132/133 ALL-DIN</b> <b>TVA-Atom</b> <b>39D</b> <b>53D</b> <b>500D</b> <b>516D</b>	<b>138 AML</b> <b>TE</b> <b>601D</b> <b>30D</b>

for lighting ballast	
85 °C	105 °C
<b>042-043 AMH-ELB</b>	<b>042-043 AHH-ELB</b>

high temperature, solid electrolyte
125 °C
<b>123 SAL-A</b>

high temperature
125 °C
<b>118 AHT</b> <b>119 AHT-DIN</b> <b>630D</b> <b>600D</b>

high temperature, low impedance
125 °C
<b>120 ATC</b>

4 terminal
105 °C
<b>604D</b>

