
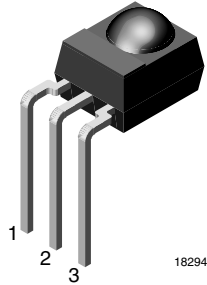



IR Receiver Modules for Remote Control Systems


AVAILABLE FOR:


- TSOP34...
- TSOP4....
- TSOP32...
- TSOP2....

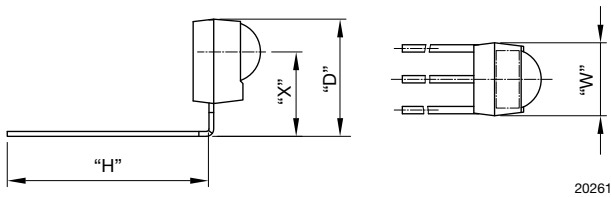


NAME	LENS AXIS (X)	VIEW	TYPE	HEIGHT (H)	WIDTH (W)	DEPTH (D)
SO1	7.4		Bend	9.6	6	10.1

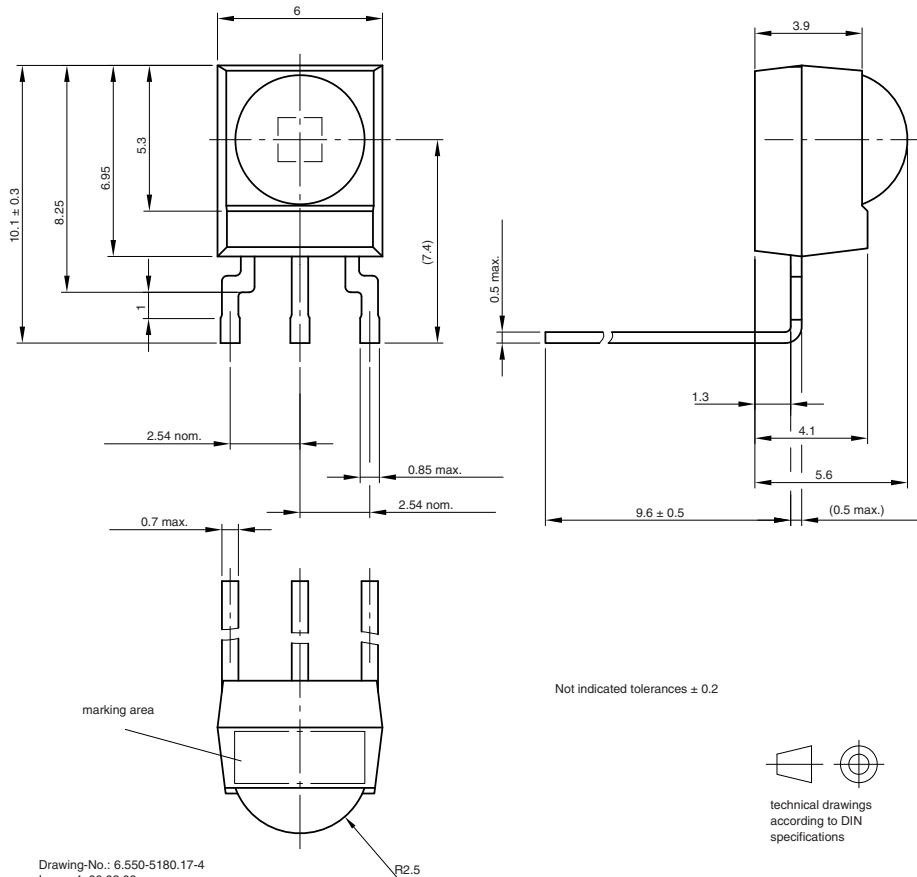MECHANICAL DIMENSIONS in millimeters


PACKAGING DIMENSIONS in millimeters

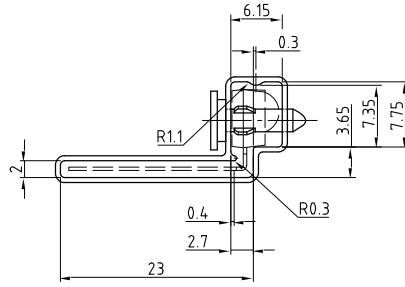


Wanddicke/wall thickness: 0.6 \pm 0.1
 Geradheit/Straightness 2
 Schnittwinkel/cut 90° ±1°
 Innenradien/inner radii max 0.5
 Geprüft nach/approved to: LV 5145

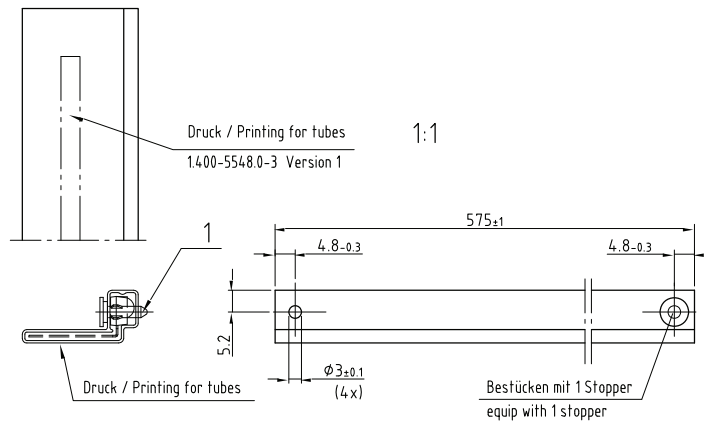

Drawing-No.: 9.700-5206.0-4
 Rev. 13; Date: 09.06.06
 20251

 ORDERING INFORMATION



2 or 3 digit product series 2 digit frequency Holder type

Note

d = "digit", please consult the list of available series on the previous page to create a valid part number.

Example: TSOP14838SO1

PACKING QUANTITY

- 90 pieces per tube
- 24 tubes per carton