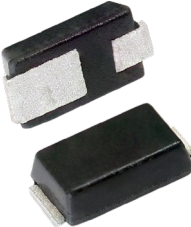


TMBS® RECTIFIERS
MicroSMP (DO-219AD)

TMBS® (Trench MOS Barrier Schottky) Rectifiers in MicroSMP (DO-219AD) Package

Device	Image	Package Type	$I_{F(AV)}$	V_{RRM}	Max. V_F at I_F		AEC-Q101	Automotive Grade
			(A)	(V)	(V)	(A)		
V1P6		MicroSMP (DO-219AD)	1	60	0.60	1.0	Yes	Yes
V1P22		MicroSMP (DO-219AD)	1	200	0.88	1.0	Yes	Yes
V1PL45		MicroSMP (DO-219AD)	1	45	0.53	1.0	Yes	Yes
V1PM10		MicroSMP (DO-219AD)	1	100	0.77	1.0	Yes	Yes
V1PM12		MicroSMP (DO-219AD)	1	120	0.87	1.0	Yes	Yes
V1PM15		MicroSMP (DO-219AD)	1	150	1.21	1.0	Yes	Yes
V2P6		MicroSMP (DO-219AD)	2	60	0.63	2.0	Yes	Yes
V2P22		MicroSMP (DO-219AD)	2	200	0.93	2.0	Yes	Yes
V2PL45		MicroSMP (DO-219AD)	2	45	0.56	2.0	Yes	Yes
V2PM10		MicroSMP (DO-219AD)	2	100	0.83	2.0	Yes	Yes
V2PM12		MicroSMP (DO-219AD)	2	120	0.98	2.0	Yes	Yes
V2PM15		MicroSMP (DO-219AD)	2	150	1.41	2.0	Yes	Yes