




# SNAP-IN ALUMINUM CAPACITORS

## 4-TERMINAL SNAP-IN DC-LINK SOLUTION

# IN A NUTSHELL

### LONG LIFETIME

299 PHL-4TSI:  
5000 h @ 105 °C


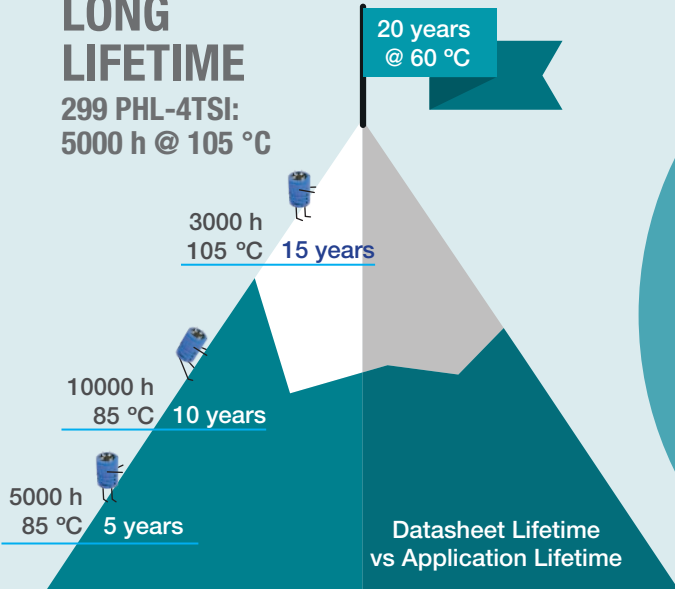


## SNAP-IN SOLUTION




## 299 PHL-4TSI

KEYED  
POLARITY  
= ONE-WAY  
MOUNTING

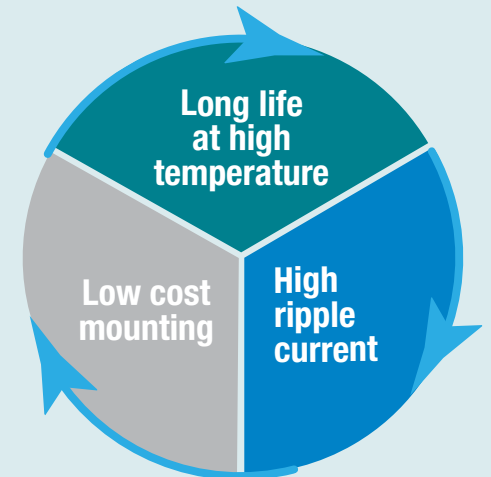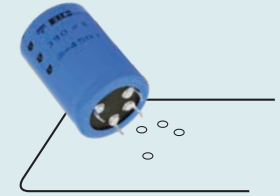

### EFFICIENT ASSEMBLY SOLDER ON HIGH CURRENT PCB

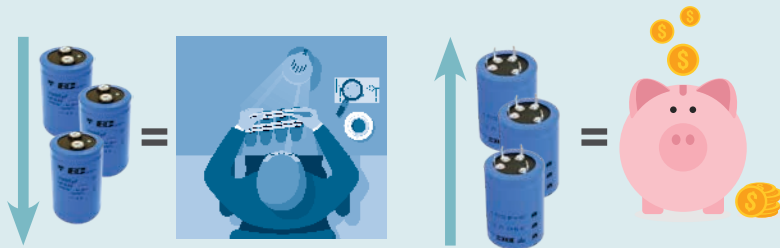

Less Manual Work Saves Time and Cost



Power  
Electronics

### SIZES BETWEEN SI AND ST

2-Pin SI (mm)	299 PHL-4TSI (mm)	ST (mm)
22 x 25	35 x 60	35 x 80
35 x 50	45 x 100	90 x 220