






AUTOMOTIVE GRADE TANTALUM CAPACITORS

HIGH PERFORMANCE, HIGH TEMPERATURE, SMALL SIZES


Voltage Derating

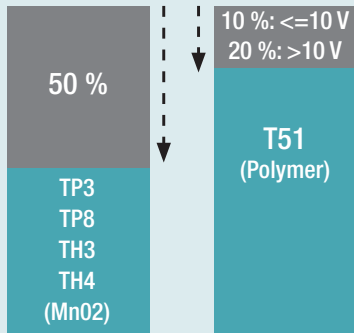

Maximum operating temperature

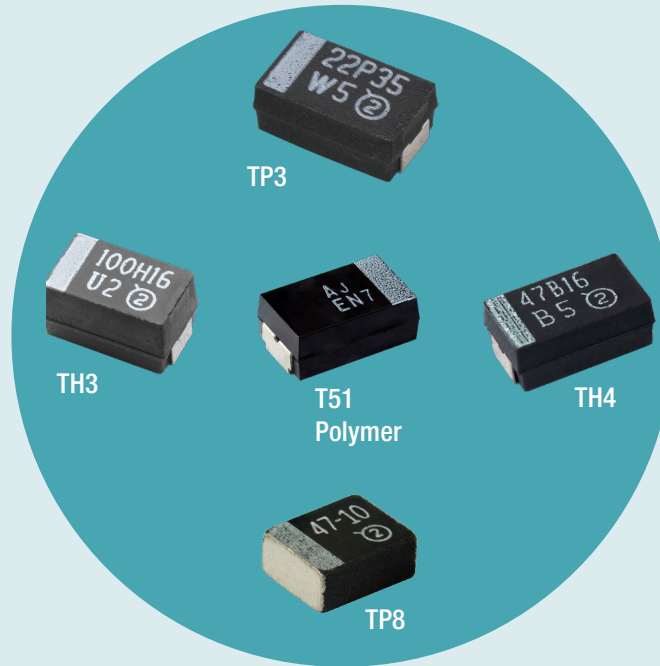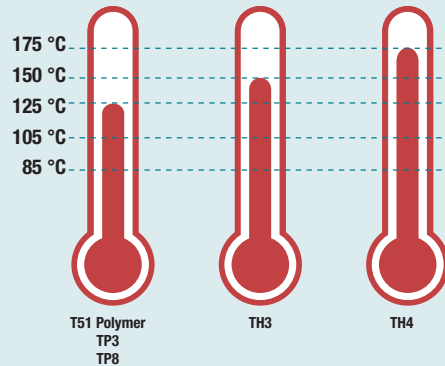

AEC-Q200
QUALIFIED
WITH PPAP
AVAILABLE

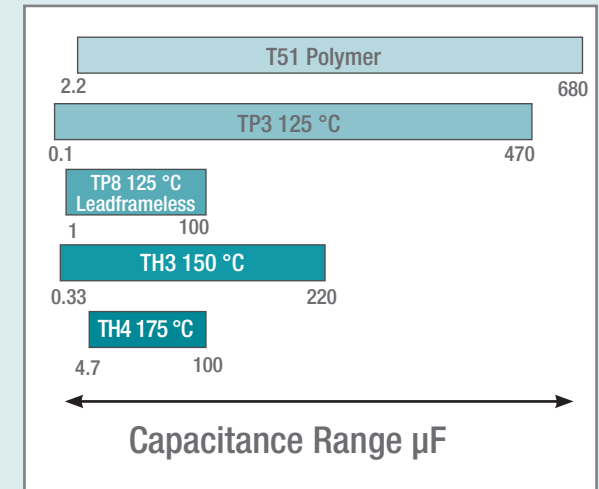

Feature	Series				
	T51	TP3	TP8	TH3	TH4
Technology	Polymer	MnO ₂	MnO ₂	MnO ₂	MnO ₂
Case Sizes	B,V,D	A-E	M,W,R,P,A,B	A-E	B-D
Voltage Ratings (V)	2.5 - 35	4 - 50	6.3 - 40	6.3 - 50	6.3 - 50
Min ESR (mΩ)	6	100	1000	150	400
Surge Current Tested	Yes	Yes	No	Yes	Yes
High CV	Best	Good	Better	Good	Good
Termination	Leadframe	Leadframe	Leadframeless	Leadframe	Leadframe