



PANEL POTENTIOMETERS: MODEL P11

The Most Versatile Modular Panel Potentiometer

MODULAR PANEL POTENTIOMETER

Various Shaft Designs
Up to 21 available designs
Lengths, diameters, machining, and custom models

Various Bushing Types
Up to 10 different bushing options
Various diameters and lengths

Sealing Level
IP64
Optional: additional panel and shaft sealing

Resistive Module
20 Ω up to 10 M Ω
Up to 7 resistive modules in one P11


Detent Modules
Higher rotating torque
CW / CCW / Central / up to 21 detents

Electrical Laws (Tapers)
Up to 6 different tapers
Most common: linear, log, and reverse log

Mr. Versatile

- Option
- Description
- Comments

Custom Friendly

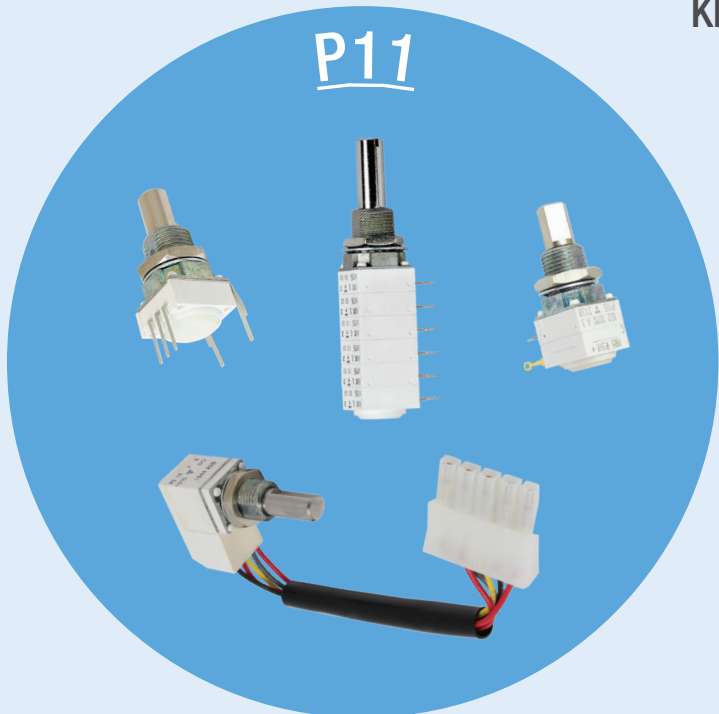

KEY APPLICATIONS

Off-Road

Welding Machines

Industrial Setting

Cockpit

Syringe Pumps


Audio

Military

30
Over
30 Years of
Experience

MULTIPLE MODELS

MODEL	SPECIFICITY	MARKETS
P11A	Low noise and GRV	Audio
P11S	Genuine model	Avionic / industrial / off-road / medical
P11H	High torque	Heavy duty vibration and shocks
P11P	High dielectric strength	High voltages
P11L	Long life cycles	Heavy duty life
T11	No shaft, knob actuated	PCB mounting

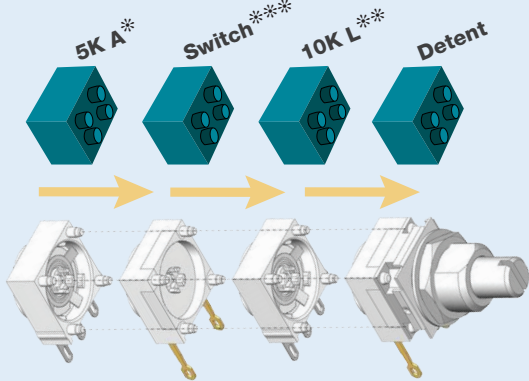

- * Resistive module 5 k Ω linear law
- ** Resistive module 10 k Ω logarithmic law
- *** Various switches available: rotary, push-push, and momentary push