



PANEL POTENTIOMETERS: MODEL P11

The Most Versatile Modular Panel Potentiometer

MODULAR PANEL POTENTIOMETER

Various Shaft Designs

Up to 21 available designs
Lengths, diameters, machining, and custom models

Various Bushing Types

Up to 10 different bushing options
Various diameters and lengths

Sealing Level

IP64
Optional: additional panel and shaft sealing; fully sealed IP67 version



Resistive Module

20 Ω up to 10 M Ω
Up to 7 resistive modules in one P11

Detent Modules

Higher rotating torque
CW / CCW / central / up to 21 detents



Custom-Friendly


Electrical Laws (Tapers)

Up to 6 different tapers
Most common: linear, log, and reverse log

Switch Modules

Rotary, momentary push, or push-push switch
RSD, RSF, RSID, RISF, RSPP, RSMP, SSMP

P11

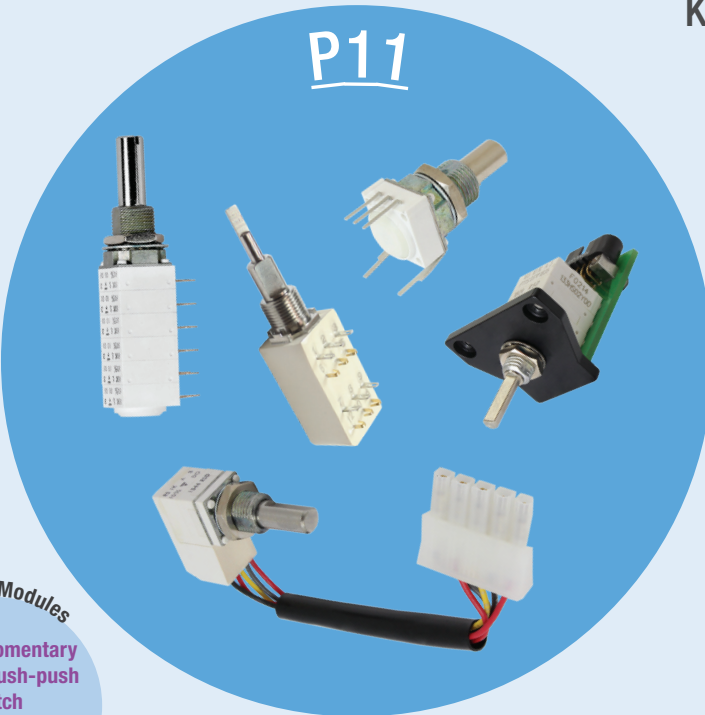

KEY APPLICATIONS



Off-Road



Welding Machines



Industrial Settings



Cockpits



Syringe Pumps



Audio




Military



MULTIPLE MODELS

MODEL	SPECIFICITY	MARKETS
P11A	Low noise and GRV	Audio
P11S	Genuine model	Avionic / industrial / off-road / medical
P11H	High torque	Heavy duty vibration and shocks
P11P	High dielectric strength	High voltages
P11L	Long life cycles	Heavy duty life
T11	No shaft, knob actuated	PCB mounting

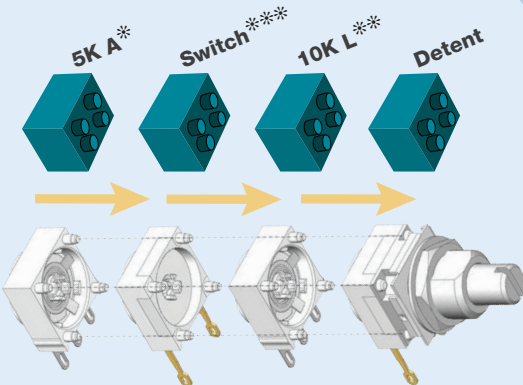

* Resistive module, 5 k Ω linear law

** Resistive module, 10 k Ω logarithmic law

*** Various switches available: rotary, push-push, and momentary push