



# LOW PROFILE, HIGH CURRENT DUAL INDUCTORS

## IHLD-4032KB-5A


- IHLD4032KBER100M5A
- IHLD4032KBER150M5A
- IHLD4032KBER220M5A
- IHLD4032KBER330M5A

## IHLD-3232HB-5A

- IHLD3232HBER5R0M5A
- IHLD3232HBER100M5A
- IHLD3232HBER150M5A
- IHLD3232HBER220M5A
- IHLD3232HBER330M5A

## IHLD-2525GG-5A

- IHLD2525GGER1R0M5A
- IHLD2525GGER4R7M5A
- IHLD2525GGER100M5A
- IHLD2525GGER150M5A
- IHLD2525GGER220M5A

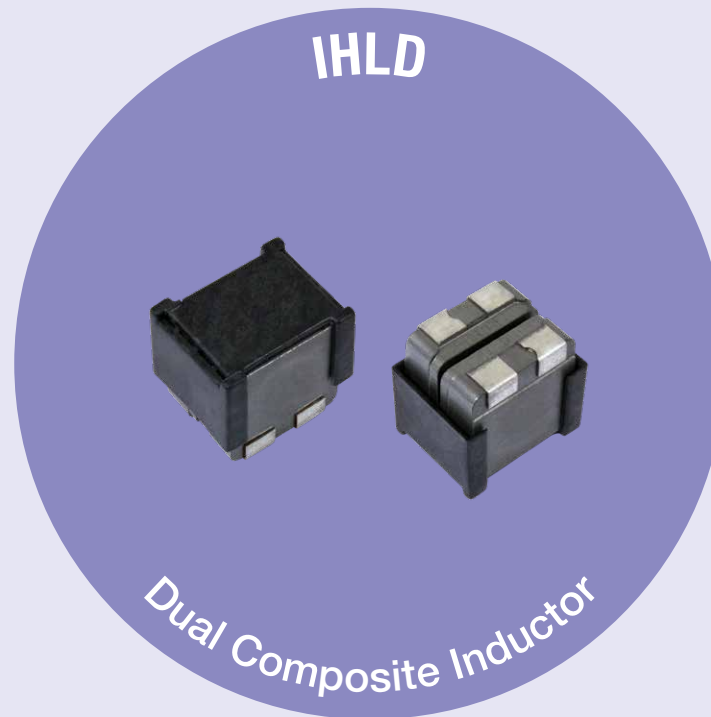


## FEATURES

- Two inductors in one package
- High temperature, up to 155 °C
- Shielded construction
- Optimal design realizes high quality sound and low distortion
- Low coupling for minimal crosstalk between inductors
- AEC-Q200 qualified



## BOTTOM VIEW

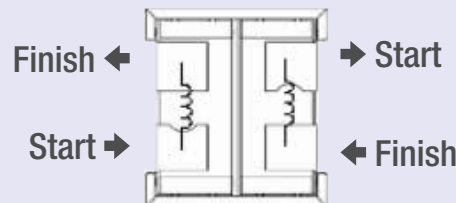

## APPLICATIONS



Class D audio amplifiers

