

Molded Inductors, Axial Leads




FEATURES

- Accurate dimensions
- Superior moisture protection
- Material categorization: for definitions of compliance please see www.vishay.com/doc?99912


RoHS
COMPLIANT

These inductors have copper winding on magnetic core structure.

DIMENSIONS in millimeters (± 0.5)

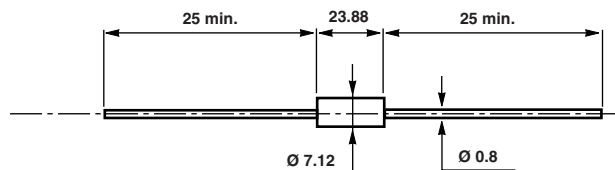

STANDARD ELECTRICAL SPECIFICATIONS

MODEL	INDUCTANCE RANGE μH	RATED POWER $P_{70^\circ\text{C}}$ W	LIMITING ELEMENT VOLTAGE V_{RMS}	TOLERANCE (1) $\pm \%$	Q RANGE	I RANGE mA
TR026	1.2 to 1000	0.750	500	10	35 to 80	170 to 3150

MECHANICAL SPECIFICATIONS

Coating	Molded epoxy
Weight	3.5 g

PACKAGING

Standard: tape and reel 500 pieces, code R10 (R)
On request: 250 pieces tape in box "ammopack", code A15 (B)

ENVIRONMENTAL SPECIFICATIONS

Operating temperature range	0 °C to +70 °C
Temperature limits	-55 °C +125 °C

MARKING

Standard:
print marked-manufacturer, inductance value, tolerance

ORDERING INFORMATION (part number)

T	R	0	2	6	1	R	5	K	R	1	0						
MODEL		STYLE				VALUE			TOLERANCE		PACKAGING			SPECIAL			
TR		026				From 1.2 μH to 1000 μH 1R5 = 1.5 μH			K: $\pm 10 \%$		R10 = reel 500 pieces On request: A15 = ammopack 250 pieces			Special code given by Vishay			

PART NUMBER DESCRIPTION (for information only)

TR	026	1.5 μH	10 %	R		e1
MODEL	STYLE	VALUE	TOLERANCE	PACKAGING	SPECIAL	LEAD (Pb)-FREE



STANDARD VALUES						
INDUCTANCE VALUE μH	TOLERANCE %	Q MIN.	TEST FREQUENCY MHz	RESISTANCE MAX. Ω	SRF MIN. MHz	I MAX. mA
1.2	± 10 %	45	7.9	0.075	170	3150
1.5	± 10 %	45	7.9	0.090	160	2850
1.8	± 10 %	45	7.9	0.135	140	2350
2.2	± 10 %	45	7.9	0.160	125	2170
2.7	± 10 %	45	7.9	0.220	115	1850
3.3	± 10 %	45	7.9	0.330	100	1500
3.9	± 10 %	45	7.9	0.450	95	1290
4.7	± 10 %	45	7.9	0.560	90	1160
5.6	± 10 %	45	7.9	0.745	80	1005
6.8	± 10 %	45	7.9	1.05	75	845
8.2	± 10 %	45	7.9	1.40	68	720
10	± 10 %	45	7.9	1.90	60	630
12	± 10 %	35	2.5	2.65	53	530
15	± 10 %	35	2.5	3.25	50	480
18	± 10 %	35	2.5	4.15	45	425
22	± 10 %	40	2.5	0.295	25	1600
27	± 10 %	50	2.5	0.32	26	1530
33	± 10 %	50	2.5	0.45	24	1290
39	± 10 %	50	2.5	0.65	22	1070
47	± 10 %	60	2.5	0.85	20	940
56	± 10 %	60	2.5	1.1	18	825
68	± 10 %	65	2.5	1.6	16	685
82	± 10 %	65	2.5	2	15	610
100	± 10 %	70	2.5	2.5	14	545
120	± 10 %	70	0.79	3.7	13	450
150	± 10 %	80	0.79	4.2	11	420
180	± 10 %	80	0.79	4.5	10	405
220	± 10 %	80	0.79	5	9	385
270	± 10 %	80	0.79	6.5	8	340
330	± 10 %	70	0.79	7.5	7.4	315
390	± 10 %	60	0.79	8.5	7	295
470	± 10 %	65	0.79	11.5	6.8	255
570	± 10 %	65	0.79	13.5	6.5	235
680	± 10 %	60	0.79	15.2	5.8	220
820	± 10 %	65	0.79	22	5	180
1000	± 10 %	65	0.79	25	4.7	170



Disclaimer

ALL PRODUCT, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE TO IMPROVE RELIABILITY, FUNCTION OR DESIGN OR OTHERWISE.

Vishay Intertechnology, Inc., its affiliates, agents, and employees, and all persons acting on its or their behalf (collectively, "Vishay"), disclaim any and all liability for any errors, inaccuracies or incompleteness contained in any datasheet or in any other disclosure relating to any product.

Vishay makes no warranty, representation or guarantee regarding the suitability of the products for any particular purpose or the continuing production of any product. To the maximum extent permitted by applicable law, Vishay disclaims (i) any and all liability arising out of the application or use of any product, (ii) any and all liability, including without limitation special, consequential or incidental damages, and (iii) any and all implied warranties, including warranties of fitness for particular purpose, non-infringement and merchantability.

Statements regarding the suitability of products for certain types of applications are based on Vishay's knowledge of typical requirements that are often placed on Vishay products in generic applications. Such statements are not binding statements about the suitability of products for a particular application. It is the customer's responsibility to validate that a particular product with the properties described in the product specification is suitable for use in a particular application. Parameters provided in datasheets and / or specifications may vary in different applications and performance may vary over time. All operating parameters, including typical parameters, must be validated for each customer application by the customer's technical experts. Product specifications do not expand or otherwise modify Vishay's terms and conditions of purchase, including but not limited to the warranty expressed therein.

Hyperlinks included in this datasheet may direct users to third-party websites. These links are provided as a convenience and for informational purposes only. Inclusion of these hyperlinks does not constitute an endorsement or an approval by Vishay of any of the products, services or opinions of the corporation, organization or individual associated with the third-party website. Vishay disclaims any and all liability and bears no responsibility for the accuracy, legality or content of the third-party website or for that of subsequent links.

Except as expressly indicated in writing, Vishay products are not designed for use in medical, life-saving, or life-sustaining applications or for any other application in which the failure of the Vishay product could result in personal injury or death. Customers using or selling Vishay products not expressly indicated for use in such applications do so at their own risk. Please contact authorized Vishay personnel to obtain written terms and conditions regarding products designed for such applications.

No license, express or implied, by estoppel or otherwise, to any intellectual property rights is granted by this document or by any conduct of Vishay. Product names and markings noted herein may be trademarks of their respective owners.