



MICRO FOOT® 3 x 2 Carrier Tape

MICRO FOOT 3 x 2 (0.5 mm pitch, 0.165 mm bump height)

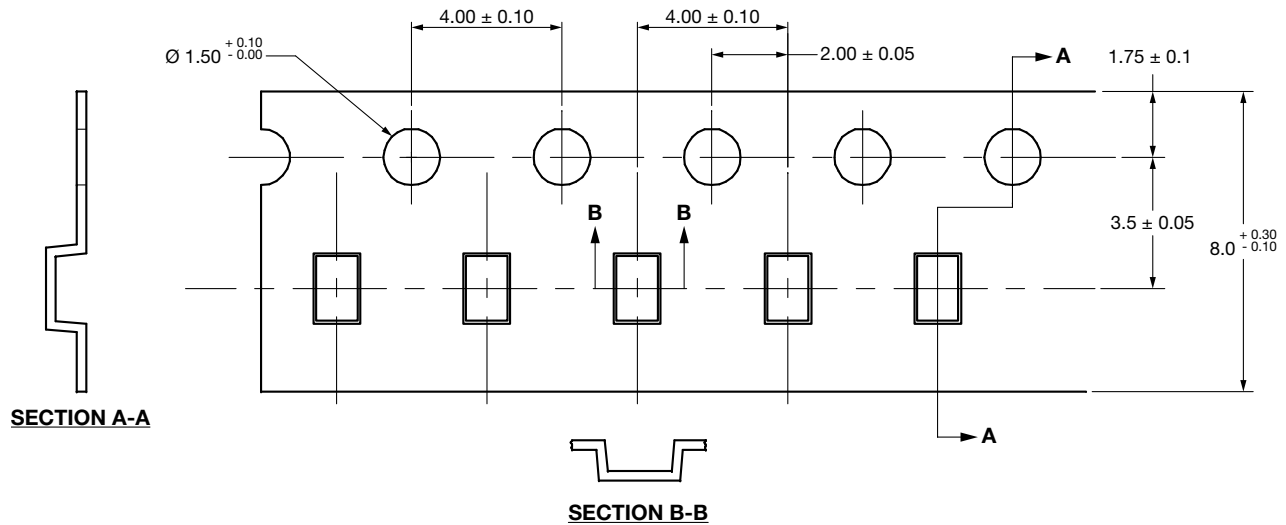

WCSP6: 6 BUMPS (2 x 3, 0.5 mm pitch, 250 µm bump height, 1 mm x 1.5 mm die size)

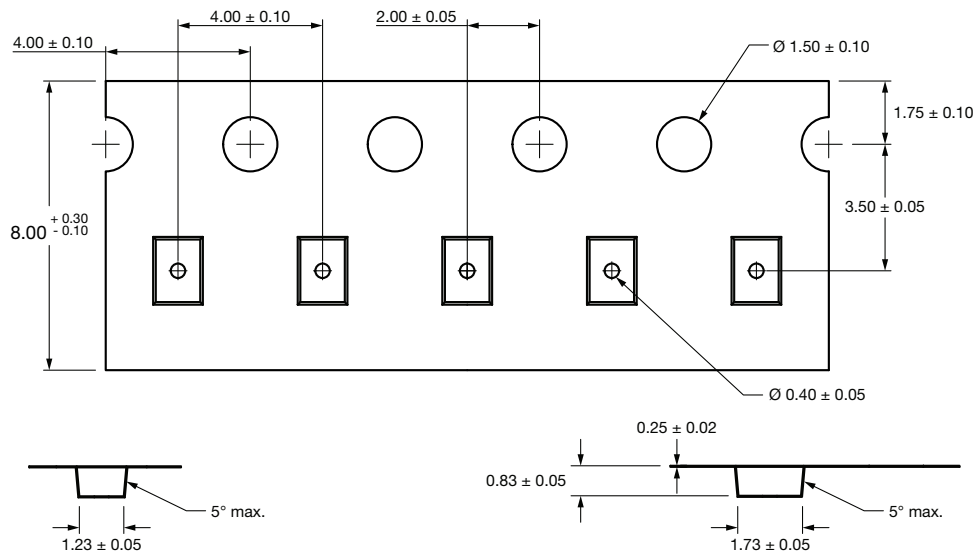

Notes

- (1) 10 sprocket hole pitch cumulative tolerance ± 0.2 mm
- (2) Camber not to exceed 1 mm in 100 mm
- (3) Material: black conductive or black static dissipative
- (4) It should be measured from:
 - a. sprocket hole to pocket center and
 - b. sprocket hole to pocket hole
- (5) All sizes in mm unless specified
- (6) Use seal tape with 9.3 mm width (see note 8, drawing 92-5210-x)
- (7) WCSP6 is using 3M058821

QUANTITY PER REEL	
T1	3000
ECN: E21-0454-Rev. F, 30-Aug-2021 DWG: 93-5221-X	