


### DPAK (TO-252AA) - (AEC-Q101 qualified)

#### CARRIER TAPE FOR TAPE AND REEL LEFT in millimeters

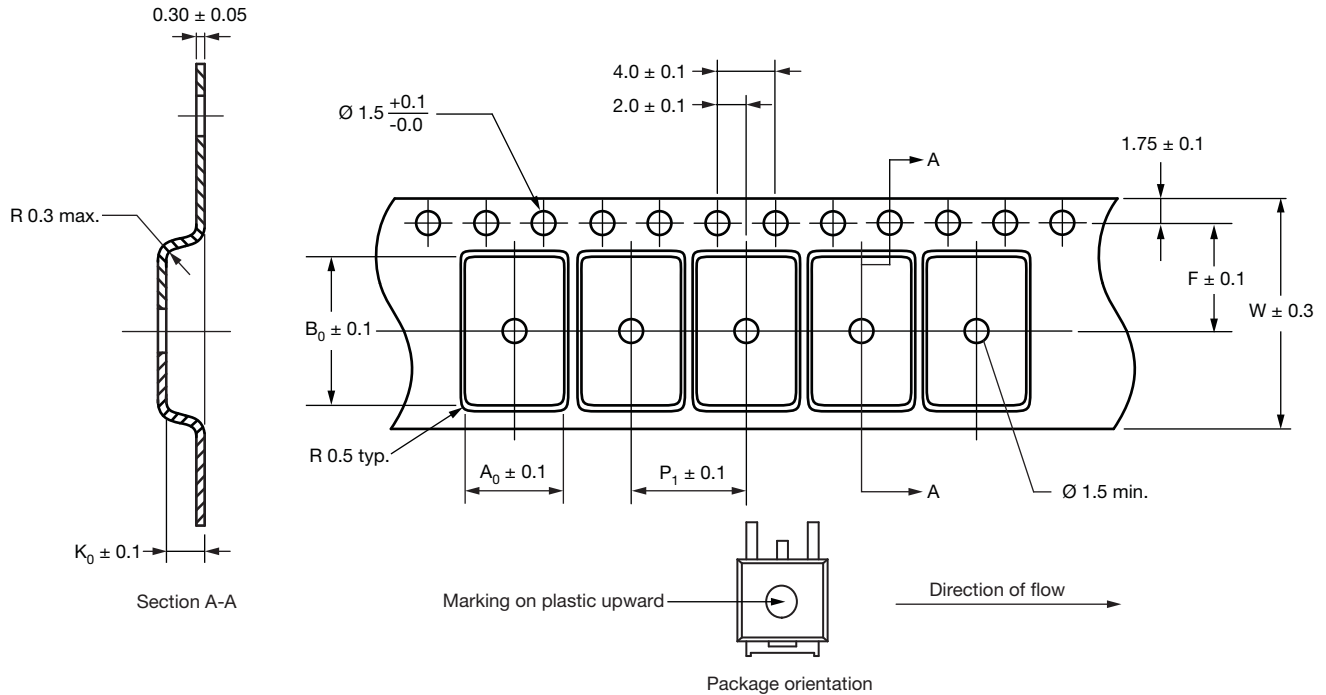


PACKAGE	A <sub>0</sub>	B <sub>0</sub>	K <sub>0</sub>	F	P <sub>1</sub>	W	REEL DIAMETER	QUANTITY PER REEL
DPAK (TO-252AA)	6.90	10.50	2.65	7.50	8.0	16.0	330	3000

#### Note

(1) For dimensions, see below


#### COVER TAPE FOR CARRIER TAPE in millimeters

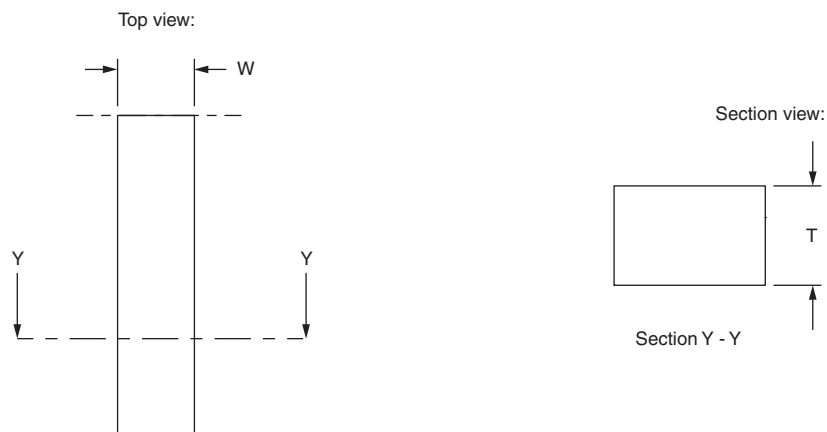

APPLICATION	COVER TAPE WIDTH W	COVER TAPE THICKNESS T	CARRIER TAPE WIDTH	MATERIAL
DPAK (TO-252AA)	13.3 ± 0.1	0.06 ± 0.02	16.0 ± 0.3	Antistatic / treated / transparent / polyester



### CARRIER TAPE AND REEL PACKAGING DPAK (TO-252AA) - (AEC-Q101 qualified)

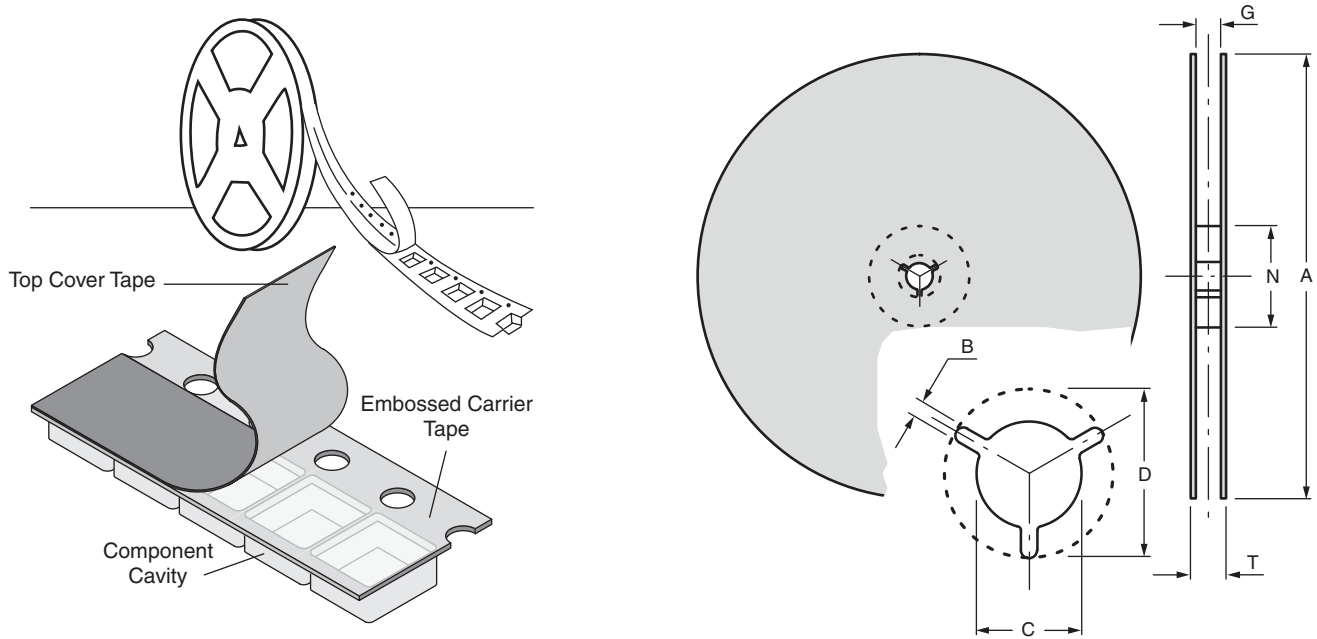

DIMENSIONS in millimeters							
CARRIER TAPE SIZE	A	B	C	D MIN.	N	G	T MAX.
16 mm	330 ± 2.0	2.20 ± 0.3	13.0 + 0.5/-0.2	20.2	100 ± 0.2	16.4 +2.0/-0.0	23.4